

Part No: 3729-794E

Fabricated DWV

Couplings

Desc: 18X14 PVC RED COUP SOC ECC SCH40

MSRP: 1204.48

Part Code: 390

Weight(lbs): 49.075

Weight(kg): 22.26

Weight(gm): 22260


Size: 18 X 14

Color: WHITE

Material: PVC

Schedule SCH 40 DWV- Eccentric Reducer

Connection Socket x Socket

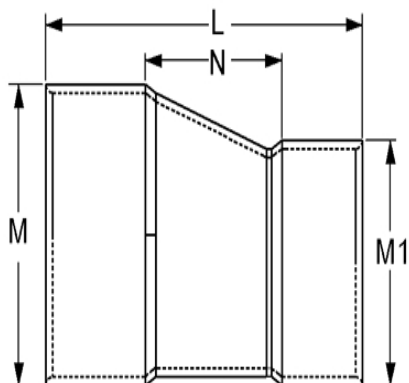

M = 19

M1 = 14-7/8

L = 34-1/8

N = 18-1/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

