

Part No: 3729-912

Fabricated DWV

Couplings

Desc: 24X12 PVC RED COUPLING SOC SCH40

MSRP: 3564.62

Part Code: 390

Weight(lbs): 108.578

Weight(kg): 49.25

Weight(gm): 49250


Size: 24 X 12

Color: WHITE

Material: PVC

Schedule SCH 40 DWV - Reducing

Connection Socket x Socket

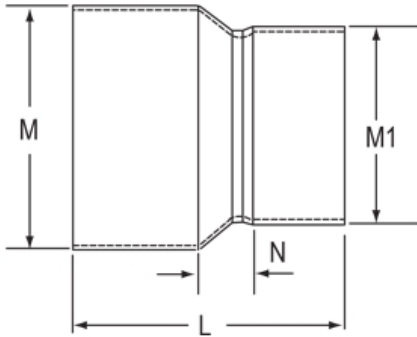

N = 30-7/8

L = 49-1/8

M = 25-3/16

M1 = 13-3/4

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

