

Part No: 3729-920

Fabricated DWV

Couplings

Desc: 24X20 PVC RED COUPLING SOC SCH40

MSRP: 2065.92

Part Code: 390

Weight(lbs): 66.998

Weight(kg): 30.39

Weight(gm): 30390


Size: 24 X 20

Color: WHITE

Material: PVC

Schedule SCH 40 DWV - Reducing

Connection Socket x Socket

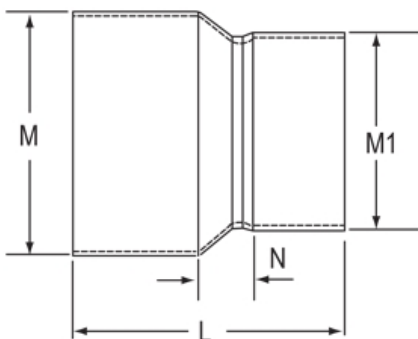

L = 28-3/4

M = 25-3/16

M1 = 21-3/16

N = 6-3/4

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

