

Part No: 3742-060

Fabricated DWV

Elbows

Desc: 6 PVC 22-1/2 ST ELL SPGXSOC SCH40

MSRP: 115.96

Part Code: 390

Weight(lbs): 2.601

Weight(kg): 1.18

Weight(gm): 1180

Size: 6


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Connection Spigot x Socket

Angle 22-1/2° Street

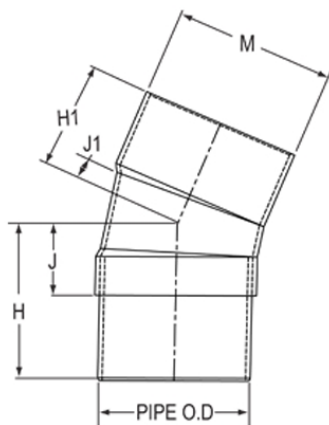

H = 6-3/4

H1 = 3-1/8

J = 2-3/4

J1 = 1/8

M1 = 7-3/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

