

Part No: 3742-160

Fabricated DWV

Elbows

Desc: 16 PVC 22-1/2 ST EL SPGXSOC SCH40

MSRP: 724

Part Code: 390

Weight(lbs): 32.858

Weight(kg): 14.904

Weight(gm): 14904

Size: 16


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Connection Spigot x Socket

Angle 22-1/2° Street

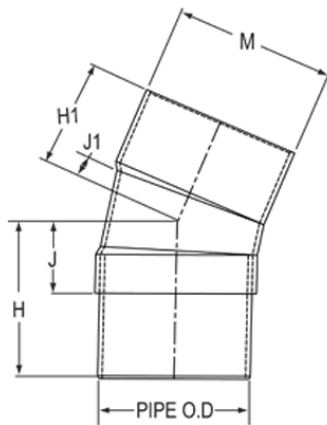

H = 16-7/8

H1 = 6-1/16

J = 7-7/8

J1 = 1-15/16

M1 = 17

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

