

Part No: 3763-762

Fabricated DWV

Glue-on Saddles

Desc: 16X12 PVC SADDLE SOC SCH40 N.P.R.

MSRP: 424

Part Code: 390

Weight(lbs): 11.177

Weight(kg): 5.07

Weight(gm): 5070


Size: 16 X 12

Color: WHITE

Material: PVC

Schedule SCH 40 DWV Saddle

Connection Socket

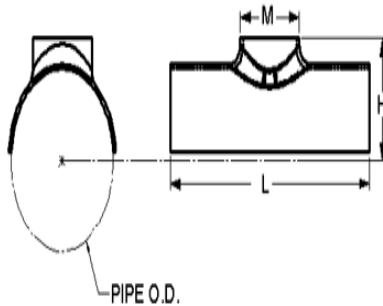

H = 10-1/2

L = 20-3/4

M = 13-3/4

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

