

Part No: 3763-901

Fabricated DWV

Glue-on Saddles

Desc: 24X2 PVC SADDLE SOC SCH40 N.P.R.

MSRP: 240.77

Part Code: 390

Weight(lbs): 2.487

Weight(kg): 1.128

Weight(gm): 1128


Size: 24 X 2

Color: WHITE

Material: PVC

Schedule SCH 40 DWV Saddle

Connection Socket

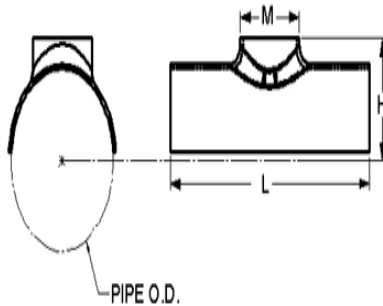

L = 9

M = 3-3/16

H = 13-5/16

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

