

Part No: 3763-914

Fabricated DWV

Glue-on Saddles

Desc: 24X14 PVC SADDLE SOC SCH40 N.P.R.

MSRP: 719.2

Part Code: 390

Weight(lbs): 31.306

Weight(kg): 14.2

Weight(gm): 14200


Size: 24 X 14

Color: WHITE

Material: PVC

Schedule SCH 40 DWV Saddle

Connection Socket

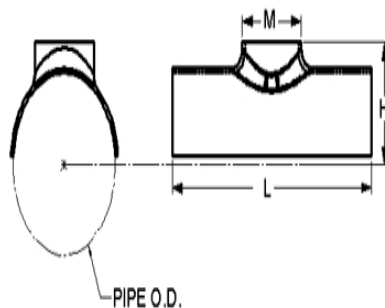

H = 14-5/8

L = 24

M = 15

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

