

Part No: 3765-694

Fabricated DWV

Glue-on Saddles

Desc: 14X4 PVC STUB SDDLE SOC SCH40 NPR

MSRP: 177.71

Part Code: 390

Weight(lbs): 4.497

Weight(kg): 2.04

Weight(gm): 2040


Size: 14 X 4

Color: WHITE

Material: PVC

Schedule SCH 40 DWV Stub Saddle

Connection Socket

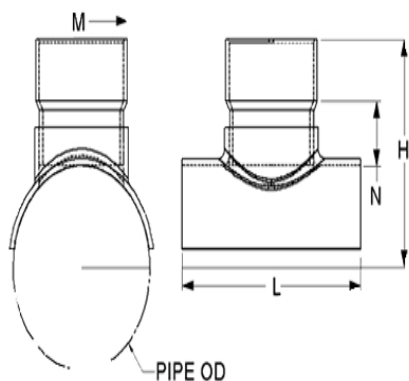

H = 12-9/16

L = 12

M = 5

N = 3-5/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

