

Part No: 3765-792

Fabricated DWV

Glue-on Saddles

Desc: 18X12 PVC STUB SADDLE SOC SCH40 N.P.R.

MSRP: 495.98

Part Code: 390

Weight(lbs): 22.818

Weight(kg): 10.35

Weight(gm): 10350


Size: 18 X 12

Color: WHITE

Material: PVC

Schedule SCH 40 DWV Stub Saddle

Connection Socket

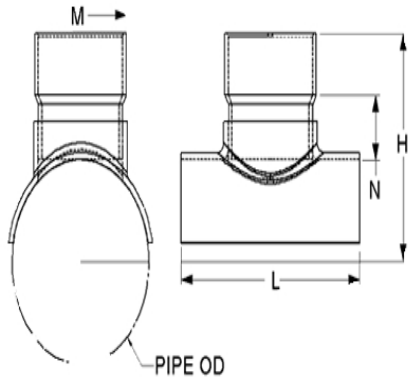

H = 19-1/4

L = 20-3/4

M = 13-9/16

N = 4-3/16

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

