

Part No: 3765-816

Fabricated DWV

Glue-on Saddles

Desc: 20X6 PVC STUB SADDLE SOC SCH40 N.P.R.

MSRP: 301.38

Part Code: 390

Weight(lbs): 8.488

Weight(kg): 3.85

Weight(gm): 3850


Size: 20 X 6

Color: WHITE

Material: PVC

Schedule SCH 40 DWV Stub Saddle

Connection Socket

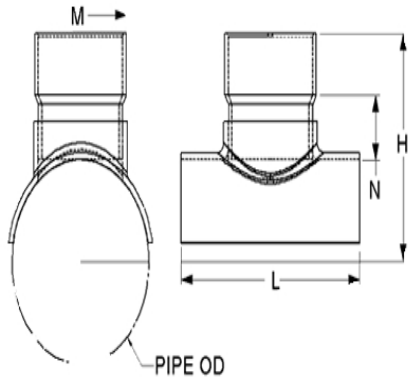

M = 7-3/16

N = 3-3/8

H = 16-5/8

L = 14-3/4

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

