

Part No: 3765-904

Fabricated DWV

Glue-on Saddles

Desc: 24X4 PVC STUB SADDLE SOC SCH40 N.P.R.

MSRP: 289.34

Part Code: 390

Weight(lbs): 5.401

Weight(kg): 2.45

Weight(gm): 2450


Size: 24 X 4

Color: WHITE

Material: PVC

Schedule SCH 40 DWV Stub Saddle

Connection Socket

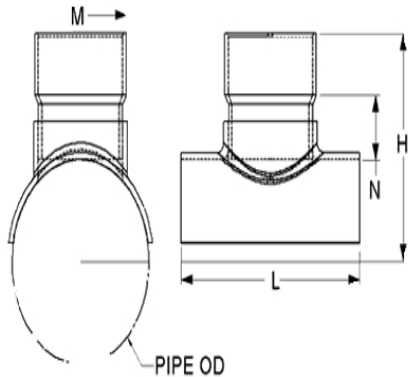

H = 17-9/16

L = 11

M = 5

N = 3-5/16

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

