

Part No: 3775-578

Fabricated DWV

Wyes

Desc: 8X2 PVC RED WYE SOC SCH40 N.P.R.

MSRP: 218.33

Part Code: 390

Weight(lbs): 9.237

Weight(kg): 4.19

Weight(gm): 4190

Size: 8 X 2


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Connection Socket X Socket X Socket

Type Reducing Wye

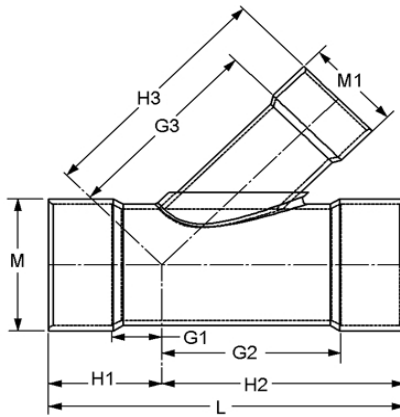

G1 = 9/16

G2 = 9-3/16

G3 = 9-3/4

H3 = 11-1/2

L = 18-1/4

M = 9-1/4

M1 = 2-11/16

H1 = 4-13/16

H2 = 13-7/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

