

Part No: 3775-582

Fabricated DWV

Wyes

Desc: 8X4 PVC RED WYE SOC SCH40 N.P.R.

MSRP: 236.32

Part Code: 390

Weight(lbs): 11.268

Weight(kg): 5.111

Weight(gm): 5111

Size: 8 X 4


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Connection Socket X Socket X Socket

Type Reducing Wye

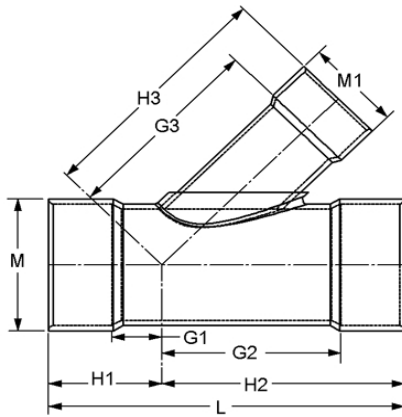

G1 = 2-1/16

G2 = 10-11/16

H1 = 6-5/16

H2 = 14-15/16

G3 = 11-7/8

H3 = 14-1/8

L = 21-1/4

M = 9-1/4

M1 = 5

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

