

Part No: 3775-585

Fabricated DWV

Wyes

Desc: 8X6 PVC RED WYE SOC SCH40 N.P.R.

MSRP: 310.14

Part Code: 390

Weight(lbs): 14.595

Weight(kg): 6.62

Weight(gm): 6620

Size: 8 X 6


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Connection Socket X Socket X Socket

Type Reducing Wye

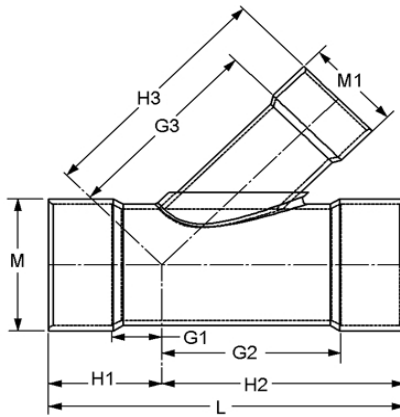

G1 = 3-1/2

G2 = 12-1/8

G3 = 12-13/16

H3 = 16-1/16

H1 = 7-3/4

H2 = 16-3/8

L = 24-1/8

M = 9- 1/4

M1 = 7-3/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

