

Part No: 3775-668

Fabricated DWV

Wyes

Desc: 12X8 PVC RED WYE SOC SCH40 N.P.R.

MSRP: 661.46

Part Code: 390

Weight(lbs): 34.357

Weight(kg): 15.584

Weight(gm): 15584

Size: 12 X 8


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Connection Socket X Socket X Socket

Type Reducing Wye

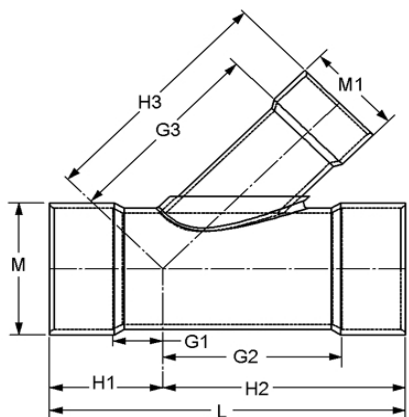

G1 = 3- 7/8

G2 = 16- 5/8

G3 = 17- 1/16

H3 = 21-5/16

L = 33

M = 13-9/16

M1 = 9-1/4

H1 = 10-1/8

H2 = 22-7/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

