

Part No: 3775-764

Fabricated DWV

Wyes

Desc: 16X14 PVC RD WYE SOC SCH40 N.P.R.

MSRP: 2308.82

Part Code: 390

Weight(lbs): 78.617

Weight(kg): 35.66

Weight(gm): 35660

Size: 16 X 14


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Connection Socket X Socket X Socket

Type Reducing Wye

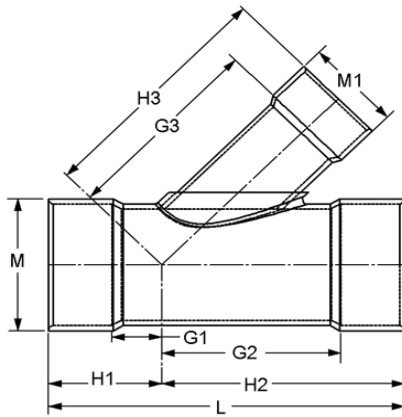

M1 = 14-7/8

H1 = 14-3/8

H2 = 30-3/8

G1 = 6-3/8

G2 = 22-3/8

G3 = 22-1/2

H3 = 29-1/2

L = 44-3/4

M = 17

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

