

Part No: 3775-820

Fabricated DWV

Wyes

Desc: 20X10 PVC RED WYE SOC SCH40 N.P.R.

MSRP: 2458.56

Part Code: 390

Weight(lbs): 103.414

Weight(kg): 46.908

Weight(gm): 46908

Size: 20 X 10


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Connection Socket X Socket X Socket

Type Reducing Wye

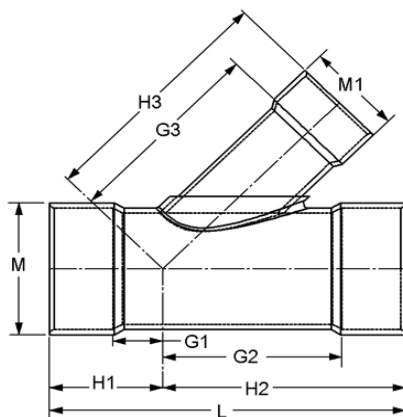

G1 = 2-3/8	G2 = 22-3/8	G3 = 23	H3 = 28-1/4	L = 44-3/4
M = 21-3/16	M1 = 11-1/2	H1 = 12-3/8	H2 = 32-3/8	

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

