

Part No: 3775-904

Fabricated DWV

Wyes

Desc: 24X4 PVC RED WYE SOC SCH40 N.P.R.

MSRP: 2749.11

Part Code: 390

Weight(lbs): 122.246

Weight(kg): 55.45

Weight(gm): 55450

Size: 24 X 4


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Connection Socket X Socket X Socket

Type Reducing Wye

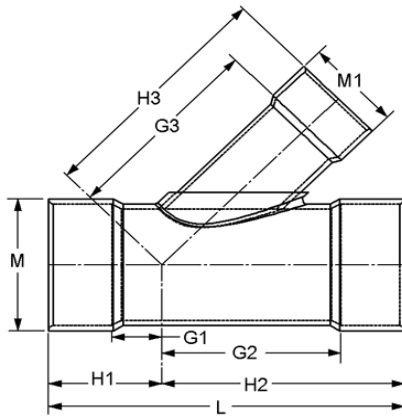

G1 = 2-7/8

G2 = 21-1/8

H2 = 33-1/8

G3 = 22-1/4

H3 = 24-1/2

L = 42-1/4

M = 25-3/8

M1 = 5

H1 = 9-1/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

