

**Part No:** 3775-920

**Fabricated DWV**

**Wyes**

**Desc:** 24X20 PVC REDWYESOCSCH40 FAB NPR.

**MSRP:** 4768.13

**Part Code:** 390

**Weight(lbs):** 234.021

**Weight(kg):** 106.15

**Weight(gm):** 106150

**Size:** 24 X 20


**Color:** WHITE

**Material:** PVC

**Schedule** SCH 40 DWV

**Connection** Socket X Socket X Socket

**Type** Reducing Wye

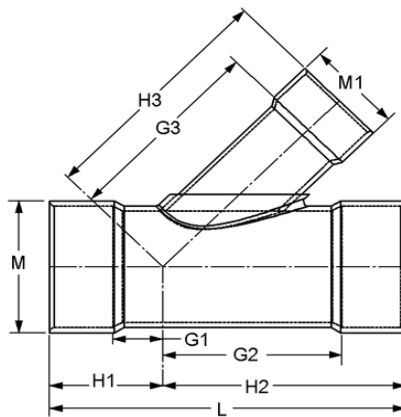

**G1** = 9-1/8

**G2** = 33-1/8

**G3** = 33

**H3** = 43

**L** = 66-1/4

**M** = 25-3/8

**M1** = 21-3/16

**H1** = 21-1/8

**H2** = 45-1/8

## Fabricated Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

**L** = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

**M** = Outside diameter of socket/thread hub; ± 1/4 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/2 inch.

**W** = Height of cap; ± 1/4 inch.

## Typical Fabricated Dimension References

