

Part No: 3776-100

Fabricated DWV

Double Wye

Desc: 10 PVC DBL-WYE SOC SCH40 N.P.R.

MSRP: 701.24

Part Code: 390

Weight(lbs): 41.469

Weight(kg): 18.81

Weight(gm): 18810

Size: 10"


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Type Standard

Connection Socket x Socket x Socket x Socket

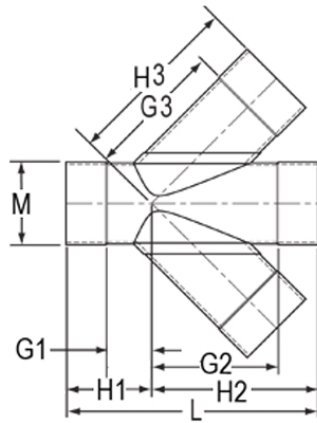

G1 = 6-9/16

G2 = 17-1/4

G3 = 17-1/4

H1 = 11-13/16

H2 = 22-1/2

H3 = 22-1/2

L = 34-5/16

M = 11-1/2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

