

Part No: 3776-160

Fabricated DWV

Double Wye

Desc: 16 PVC DBL-WYE SOC SCH40 N.P.R.

MSRP: 2665.22

Part Code: 390

Weight(lbs): 131.766

Weight(kg): 59.768

Weight(gm): 59768

Size: 16


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Type Standard

Connection Socket x Socket x Socket x Socket

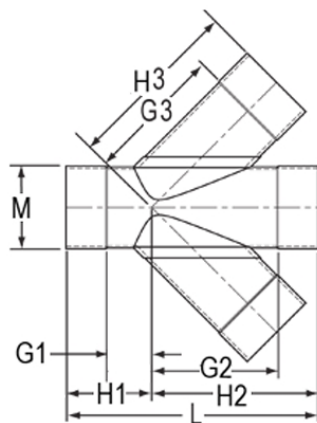

G3 = 24-3/4

H1 = 16-3/4

H2 = 32-3/4

H3 = 32-3/4

L = 49-1/2

M = 17

G1 = 8-3/4

G2 = 24-3/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

