

Part No: 3776-180

Fabricated DWV

Double Wye

Desc: 18 PVC DBL-WYE SOC SCH40 N.P.R.

MSRP: 3723.19

Part Code: 390

Weight(lbs): 187.155

Weight(kg): 84.892

Weight(gm): 84892

Size: 18


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Type Standard

Connection Socket x Socket x Socket x Socket

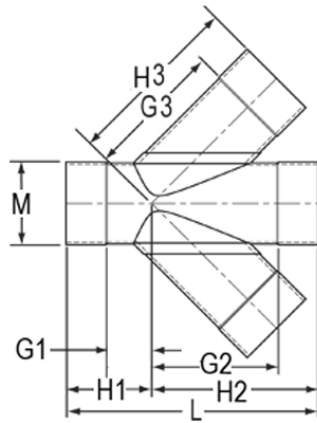

G1 = 9-7/16

G2 = 27-7/16

G3 = 27-7/16

H1 = 18-7/16

H2 = 36-7/16

H3 = 36-7/16

L = 54-7/8

M = 19-1/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

