

Part No: 3776-240

Fabricated DWV

Double Wye

Desc: 24 PVC DBL-WYE SOC SCH40 N.P.R.

MSRP: 6027.63

Part Code: 390

Weight(lbs): 471.551

Weight(kg): 213.892

Weight(gm): 213892

Size: 24"


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Type Standard

Connection Socket x Socket x Socket x Socket

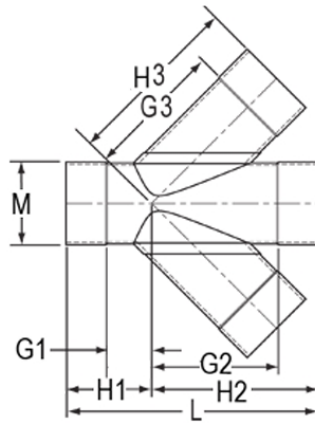

H3 = 47

L = 70

M = 25-3/8

G1 = 11

G2 = 35

G3 = 35

H1 = 23

H2 = 47

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

