

Part No: 3776-530

Fabricated DWV

Double Wye

Desc: 6X3 PVC RED DBL-WYE SOC SCH40 N.P.R.

MSRP: 188.56

Part Code: 390

Weight(lbs): 7.231

Weight(kg): 3.28

Weight(gm): 3280


Size: 6"X6"X3"X3"

Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Type Reducing

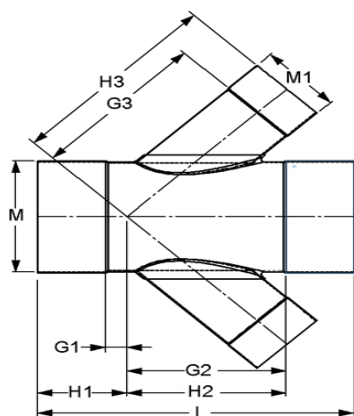

G1 = 1-13/16

G2 = 8-7/16

G3 = 9-9/16

H1 = 5-1/16

H2 = 11-11/16

H3 = 11-13/16

L = 16-3/4

M = 7-3/16

M1 = 3-15/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

