

Part No: 3776-578

Fabricated DWV

Double Wye

Desc: 8X2 PVC RED DBL-WYE SOC SCH40 N.P.R.

MSRP: 260.33

Part Code: 390

Weight(lbs): 10.152

Weight(kg): 4.605

Weight(gm): 4605

Size: 8"X8"X2"X2"


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Type Reducing

Connection Socket x Socket x Socket x Socket

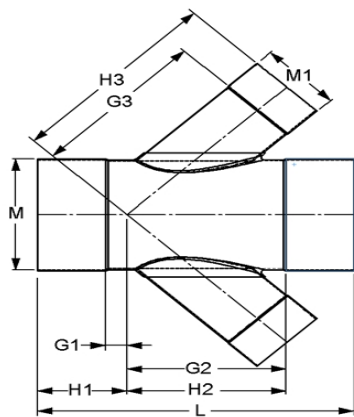

M = 9-1/4

M1 = 2-11/16

H1 = 4-13/16

H2 = 13-7/16

H3 = 11-1/2

L = 18-1/4

G3 = 9-3/4

G1 = 9/16

G2 = 9-3/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

