

Part No: 3776-670

Fabricated DWV

Double Wye

Desc: 12X10 PVC RD DBL-Y SOC S40 N.P.R.

MSRP: 1030.36

Part Code: 390

Weight(lbs): 50.149

Weight(kg): 22.747

Weight(gm): 22747

Size: 12"X12"X10"X10"


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Type Reducing

Connection Socket x Socket x Socket x Socket

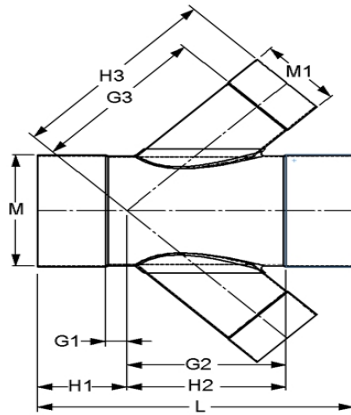

G1 = 5-3/8

G2 = 18-1/8

G3 = 18-1/8

H1 = 11-5/8

H2 = 24-3/8

H3 = 23-3/8

L = 36

M = 13-9/16

M1 = 11-1/2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

