

Part No: 3776-700

Fabricated DWV

Double Wye

Desc: 14X10 PVC RED DBL-WYE SOCSCH40 NPR

MSRP: 1439.02

Part Code: 390

Weight(lbs): 60.1

Weight(kg): 27.261

Weight(gm): 27261

Size: 14"X14"X10"X10"


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Type Reducing

Connection Socket x Socket x Socket x Socket

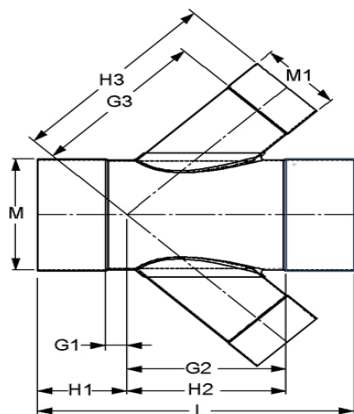

G1 = 4- 1/2

G2 = 18- 1/2

L = 37

M = 14-7/8

M1 = 11-1/2

G3 = 19

H1 = 11-1/2

H2 = 25-1/2

H3 = 23-1/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

