

Part No: 3776-753

Fabricated DWV

Double Wye

Desc: 16X3 PVC RED DBL-WYE SOC SCH40 N.P.R.

MSRP: 1326.26

Part Code: 390

Weight(lbs): 44.097

Weight(kg): 20.002

Weight(gm): 20002

Size: 16 X 3


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Type Reducing

Connection Socket x Socket x Socket x Socket

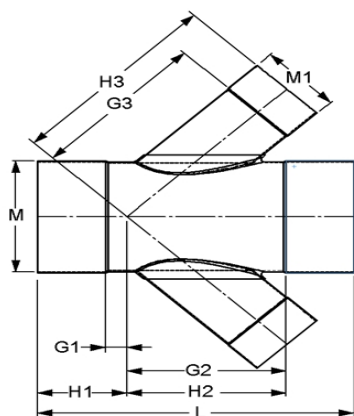

G1 = 1-1/8

G2 = 14-7/8

G3 = 15-7/8

H1 = 6-7/8

H2 = 22-7/8

H3 = 18-1/8

L = 29-3/4

M = 17

M1 = 3-15/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

