

Part No: 3776-762

Fabricated DWV

Double Wye

Desc: 16X12 PVC RD DBL-Y SOC S40 N.P.R.

MSRP: 2057.03

Part Code: 390

Weight(lbs): 85.12

Weight(kg): 38.61

Weight(gm): 38610

Size: 16 X 12


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Type Reducing

Connection Socket x Socket x Socket x Socket

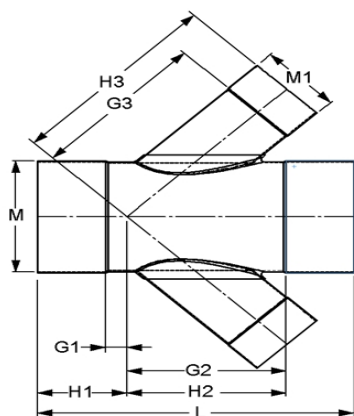

L = 43

M = 17

M1 = 13-9/16

G1 = 5-1/2

G2 = 21-1/2

G3 = 22-1/4

H1 = 13-1/2

H2 = 29-1/2

H3 = 28-1/2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

