

Part No: 3776-788

Fabricated DWV

Double Wye

Desc: 18X8 PVC RD DBL-Y SOC SCH40 N.P.R.

MSRP: 2239.32

Part Code: 390

Weight(lbs): 85.52

Weight(kg): 38.791

Weight(gm): 38791

Size: 12"X12"X8"X8"


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Type Reducing

Connection Socket x Socket x Socket x Socket

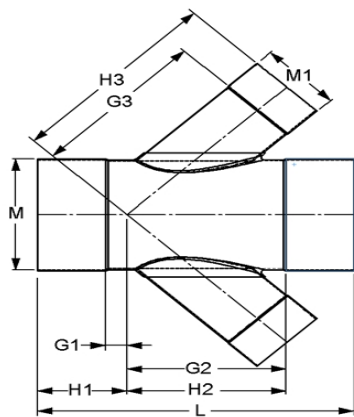

G1 = 2-3/8 **M** = 19- 1/8

M1 = 9- 1/4

G2 = 20-3/8

G3 = 20-9/16

H1 = 11-3/8

H2 = 29-3/8

H3 = 24-13/16

L = 40-3/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

