

Part No: 3776-794

Fabricated DWV

Double Wye

Desc: 18X14 PVC RED DBL-WYE SOC S40 NPR.

MSRP: 2982.12

Part Code: 390

Weight(lbs): 117.396

Weight(kg): 53.25

Weight(gm): 53250

Size: 18"X18"X14"X14"


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Type Reducing

Connection Socket x Socket x Socket x Socket

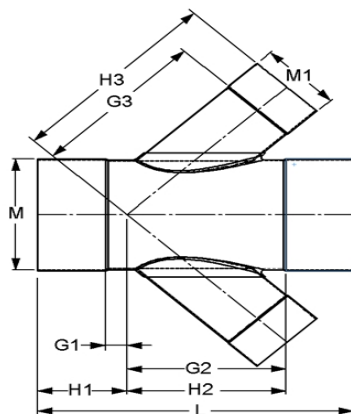

G1 = 5-3/8

G2 = 23-3/8

G3 = 23-13/16

H1 = 14-3/8

H2 = 32-3/8

H3 = 30-13/16

L = 46-3/4

M = 19-1/8

M1 = 14-7/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

