

Part No: 3776-820

Fabricated DWV

Double Wye

Desc: 20X10 PVC RD DBL-WYE SOC S40 NPR.

MSRP: 3282.18

Part Code: 390

Weight(lbs): 110.128

Weight(kg): 49.953

Weight(gm): 49953

Size: 20"X20"X10"X10"


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Type Reducing

Connection Socket x Socket x Socket x Socket

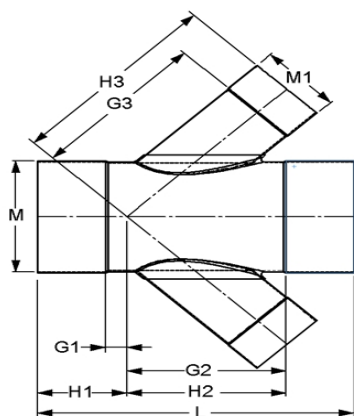

G1 = 2-3/8

G2 = 22-3/8

G3 = 23

H1 = 12-3/8

H2 = 32-3/8

H3 = 28-1/4

L = 44-3/4

M = 21-3/16

M1 = 11-1/2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

