

Part No: 3776-904

Fabricated DWV

Double Wye

Desc: 24X4 PVC RED DBL-WYE SOC SCH40 N.P.R.

MSRP: 3002.97

Part Code: 390

Weight(lbs): 126.565

Weight(kg): 57.409

Weight(gm): 57409

Size: 24"X24"X4"X4"


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Type Reducing

Connection Socket x Socket x Socket x Socket

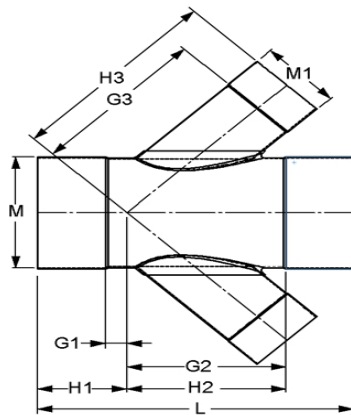

H2 = 33-1/8

H3 = 24-1/2

L = 42-1/4

M = 25-3/8

M1 = 5

G1 = 2-7/8

G2 = 21-1/8

G3 = 22-1/4

H1 = 9-1/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

