

Part No: 3776-906

Fabricated DWV

Double Wye

Desc: 24X6 PVC RED DBL-WYE SOC S40 NPR

MSRP: 3320.24

Part Code: 390

Weight(lbs): 137.8

Weight(kg): 62.505

Weight(gm): 62505

Size: 24"X24"X6"X6"


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Type Reducing

Connection Socket x Socket x Socket x Socket

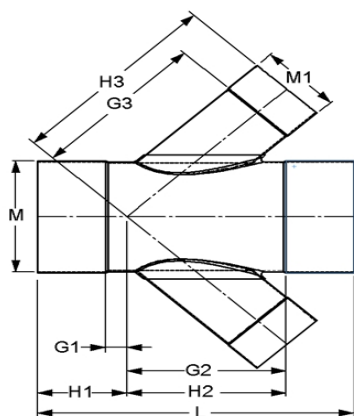

G1 = 1-1/4

G2 = 22-3/4

G3 = 23-3/16

H1 = 10-3/4

H2 = 34-3/4

H3 = 26-7/16

L = 45-1/2

M = 25-3/8

M1 = 7-3/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

