

Part No: 3776-914

Fabricated DWV

Double Wye

Desc: 24X14 PVC RED DBL-WYE SOC S40 NPR

MSRP: 4032.18

Part Code: 390

Weight(lbs): 201.569

Weight(kg): 91.43

Weight(gm): 91430

Size: 24"X24"X14"X14"


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Type Reducing

Connection Socket x Socket x Socket x Socket

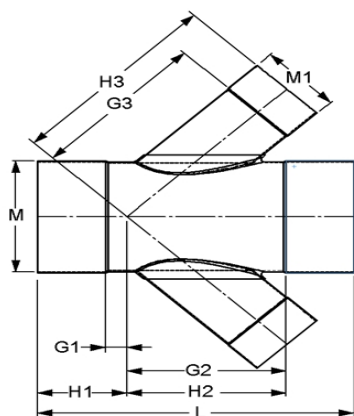

G1 = 4

G2 = 28

G3 = 27-7/8

H1 = 16

H2 = 40

H3 = 34-7/8

L = 56

M = 25-3/8

M1 = 14-7/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

