

Part No: 3776-918

Fabricated DWV

Double Wye

Desc: 24X18 PVC RD DBL-WYE SOC S40 N.PR

MSRP: 4430.34

Part Code: 390

Weight(lbs): 272.82

Weight(kg): 123.749

Weight(gm): 123749

Size: 24"X24"X18"X18"


Color: WHITE

Material: PVC

Schedule SCH 40 DWV

Type Reducing

Connection Socket x Socket x Socket x Socket

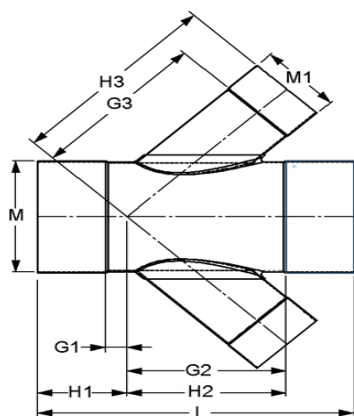

H1 = 19-7/8

H2 = 43-7/8

H3 = 40-1/2

L = 63-3/4

M = 25-3/8

M1 = 19-1/8

G1 = 7-7/8

G2 = 31-7/8

G3 = 31-1/2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

