

**Part No:** 3777-080

**Fabricated DWV**

**Combo Wye & 1/8 Bend**

**Desc:** 8 PVC COMB WYE&1/8 BEND SOC SCH40

**MSRP:** 502.93

**Part Code:** 390

**Weight(lbs):** 24.074

**Weight(kg):** 10.92

**Weight(gm):** 10920


**Size:** 8

**Color:** WHITE

**Material:** PVC

**Schedule** SCH 40 DWV - Standard

**Connection** Socket x Socket x Socket

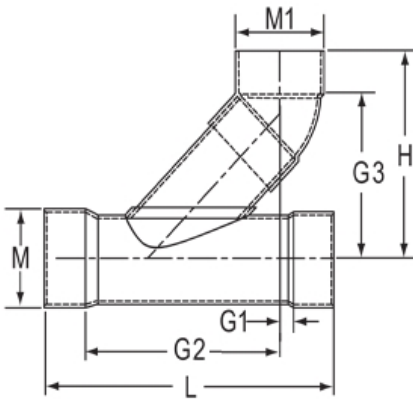

**G1** = 3/16

**G2** = 19-3/4

**G3** = 16-1/8

**H** = 20-1/8

**L** = 28-7/16

**M** = 9-1/4

**M1** = 9-3/8

## Fabricated Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

**L** = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

**M** = Outside diameter of socket/thread hub; ± 1/4 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/2 inch.

**W** = Height of cap; ± 1/4 inch.

## Typical Fabricated Dimension References

