

Part No: 3777-140

Fabricated DWV

Combo Wye & 1/8 Bend

Desc: 14 PVC COMB Y&1/8 BEND SOC SCH40

MSRP: 2258.81

Part Code: 390

Weight(lbs): 79.344

Weight(kg): 35.99

Weight(gm): 35990


Size: 14

Color: WHITE

Material: PVC

Schedule SCH 40 DWV - Standard

Connection Socket x Socket x Socket

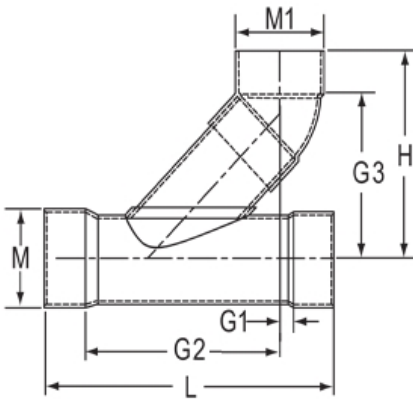

G1 = 1-1/4

G2 = 29-5/8

G3 = 29-5/16

H = 36-5/16

L = 42-3/8

M = 14-7/8

M1 = 14-7/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

