

Part No: 3777-180

Fabricated DWV

Combo Wye & 1/8 Bend

Desc: 18PVC COMB WYE&1/8 BEND SOC SCH40

MSRP: 3340.14

Part Code: 390

Weight(lbs): 169.536

Weight(kg): 76.9

Weight(gm): 76900


Size: 18

Color: WHITE

Material: PVC

Schedule SCH 40 DWV - Standard

Connection Socket x Socket x Socket

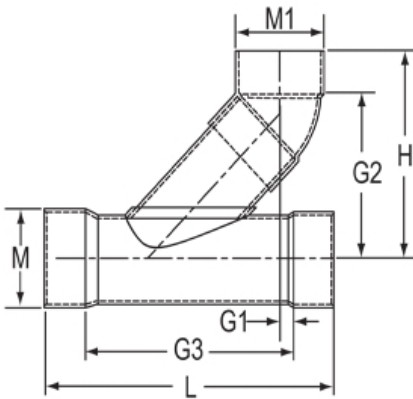

G1 = 1-3/8

G2 = 38-1/4

G3 = 36-9/16

H = 45-9/16

L = 54-7/8

M = 19-1/8

M1 = 19-1/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

