

Part No: 3777-200

Fabricated DWV

Combo Wye & 1/8 Bend

Desc: 20 PVC COMB WYE&1/8 BEND SOC SCH40

MSRP: 4328.12

Part Code: 390

Weight(lbs): 210.542

Weight(kg): 95.5

Weight(gm): 95500


Size: 20

Color: WHITE

Material: PVC

Schedule SCH 40 DWV - Standard

Connection Socket x Socket x Socket

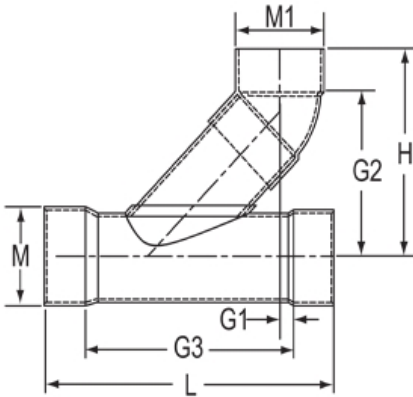

G1 = 1-13/16

G2 = 43-9/16

G3 = 41-7/16

H = 51-7/16

L = 61-3/4

M = 21-3/16

M1 = 21-3/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

