

Part No: 3777-585

Fabricated DWV

Combo Wye & 1/8 Bend

Desc: 8X6 PVC COMB WYE&1/8BND SOC SCH40

MSRP: 396.69

Part Code: 390

Weight(lbs): 16.755

Weight(kg): 7.6

Weight(gm): 7600


Size: 8"X8"X6"

Color: WHITE

Material: PVC

Schedule SCH 40 DWV- Reducing

Connection Socket x Socket x Socket

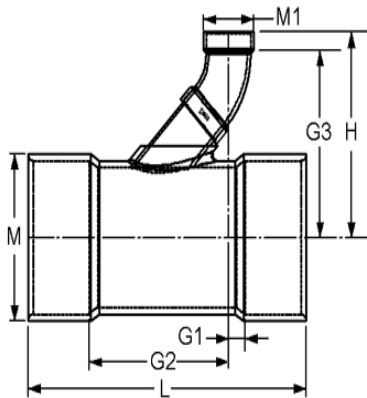

G1 = 7/16

G2 = 15-3/16

G3 = 13-11/16

H = 16-11/16

L = 24-1/8

M = 9-1/4

M1 = 7-1/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

