

Part No: 3777-621

Fabricated DWV

Combo Wye & 1/8 Bend

Desc: 10X2 PVC RED COMB WYE&1/8 BEND SOC SCH40

MSRP: 410.26

Part Code: 390

Weight(lbs): 14.065

Weight(kg): 6.38

Weight(gm): 6380


Size: 10"X10"X2"

Color: WHITE

Material: PVC

Schedule SCH 40 DWV- Reducing

Connection Socket x Socket x Socket

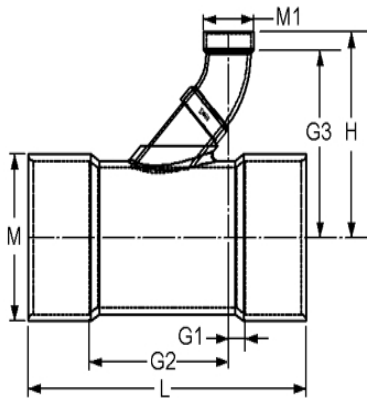

G1 = 1-3/8

G2 = 8-3/8

G3 = 10-5/16

H = 11-1/16

L = 20-1/4

M = 11-1/2

M1 = 2-3/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

