

Part No: 3777-626

Fabricated DWV

Combo Wye & 1/8 Bend

Desc: 10X6 PVC RD CMB Y&1/8BEND SOC S40

MSRP: 552.53

Part Code: 390

Weight(lbs): 24.273

Weight(kg): 11.01

Weight(gm): 11010


Size: 10"X10"X6"

Color: WHITE

Material: PVC

Schedule SCH 40 DWV- Reducing

Connection Socket x Socket x Socket

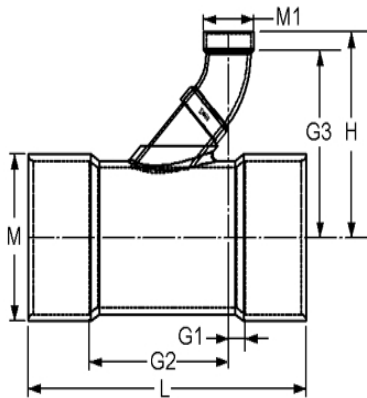

G1 = 1-9/16

G2 = 16-3/16

G3 = 14-11/16

H = 17-11/16

L = 28-1/4

M = 11-1/2

M1 = 7-1/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

