

Part No: 3777-628

Fabricated DWV

Combo Wye & 1/8 Bend

Desc: 10X8 PVC RD CMB Y&1/8BEND SOC S40

MSRP: 687.48

Part Code: 390

Weight(lbs): 31.628

Weight(kg): 14.346

Weight(gm): 14346


Size: 10"X10"X8"

Color: WHITE

Material: PVC

Schedule SCH 40 DWV- Reducing

Connection Socket x Socket x Socket

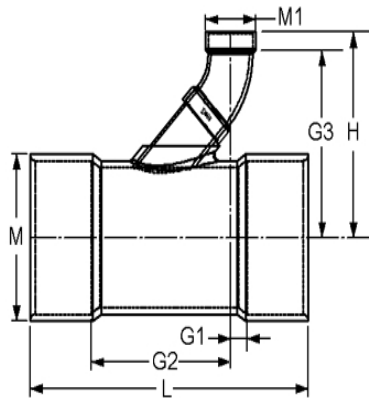

G1 = 3/4

G2 = 20- 1/4

G3 = 17-1/8

H = 21-3/16

L = 31-1/2

M = 11-1/2

M1 = 9-3/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

