

Part No: 3777-754

Fabricated DWV

Combo Wye & 1/8 Bend

Desc: 16X4 PVC RD CMB WYE&1/8 BND S S40

MSRP: 1355.86

Part Code: 390

Weight(lbs): 43.1

Weight(kg): 19.55

Weight(gm): 19550


Size: 16 X 4

Color: WHITE

Material: PVC

Schedule SCH 40 DWV- Reducing

Connection Socket x Socket x Socket

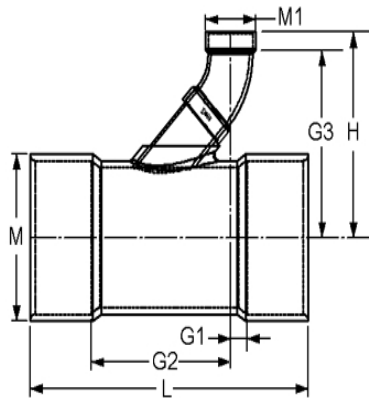

G2 = 13-1/8

G3 = 15-3/4

H = 17-9/16

L = 31

M = 17

M1 = 5-1/16

G1 = 1-7/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

