

Part No: 3777-826

Fabricated DWV

Combo Wye & 1/8 Bend

Desc: 20X16 PVC RED COMB WYE&1/8 BND SOC SCH40

MSRP: 3856.14

Part Code: 390

Weight(lbs): 165.148

Weight(kg): 74.91

Weight(gm): 74910


Size: 20 X 16

Color: WHITE

Material: PVC

Schedule SCH 40 DWV- Reducing

Connection Socket x Socket x Socket

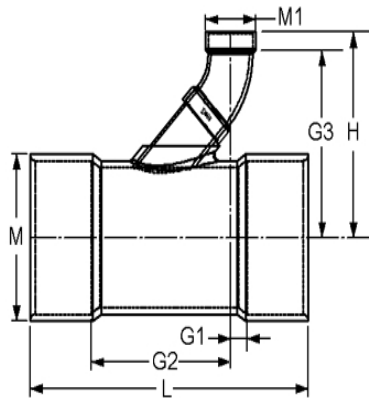

M1 = 17

G1 = 1-1/8

G2 = 32-3/4

G3 = 34-7/8

H = 42-7/8

L = 52-3/4

M = 21-3/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

