

Part No: 3777-916

Fabricated DWV

Combo Wye & 1/8 Bend

Desc: 24X16 PVC RED COMB WYE&1/8 BND SOC SCH40

MSRP: 4801.81

Part Code: 390

Weight(lbs): 224.201

Weight(kg): 101.696

Weight(gm): 101696


Size: 24 X 16

Color: WHITE

Material: PVC

Schedule SCH 40 DWV- Reducing

Connection Socket x Socket x Socket

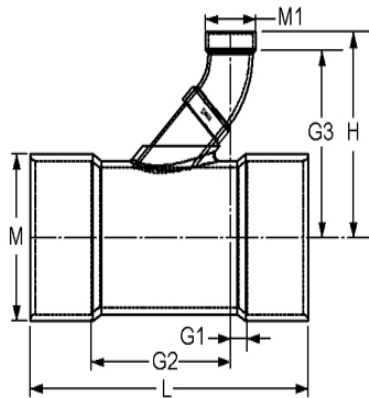

L = 60-3/4

M = 25-3/8

M1 = 17

G1 = 15/16

G2 = 35-13/16

G3 = 36-13/16

H = 44-13/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

