

Part No: 3790-100

Fabricated DWV

Sanitary Tee

Desc: 10 PVC SAN TEE SOC SCH40 NPR

MSRP: 888.4

Part Code: 390

Weight(lbs): 37.071

Weight(kg): 16.815

Weight(gm): 16815


Size: 10"

Color: WHITE

Material: PVC

Type Sch 40 DWV

Connection Socket X Socket X Socket

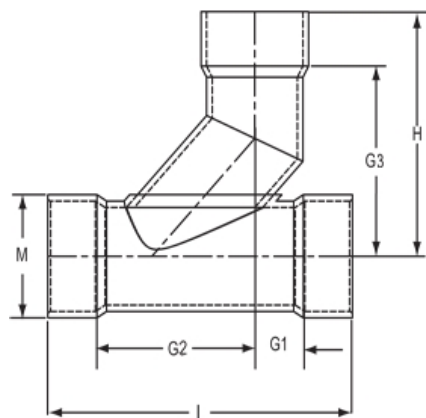

G1 = 6-9/16

G2 = 17-1/4

G3 = 19-1/8

H = 24-3/8

L = 34-5/16

M = 11-1/2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

