

Part No: 3790-120

Fabricated DWV

Sanitary Tee

Desc: 12 PVC SAN TEE SOC SCH40 N.P.R.

MSRP: 1272.13

Part Code: 390

Weight(lbs): 58.423

Weight(kg): 26.5

Weight(gm): 26500


Size: 12"

Color: WHITE

Material: PVC

Type Sch 40 DWV

Connection Socket X Socket X Socket

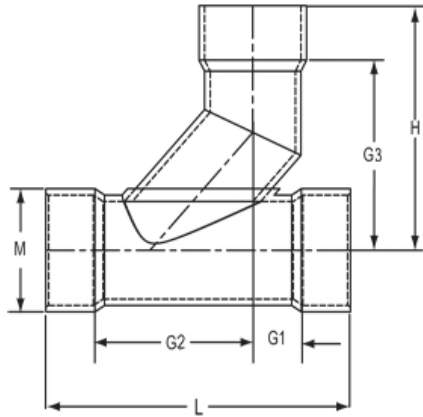

G3 = 21-13/16

H = 28-1/16

L = 39-7/8

M = 13-9/16

G1 = 5-5/8

G2 = 21-3/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

